


1485B4N Cut Sheet

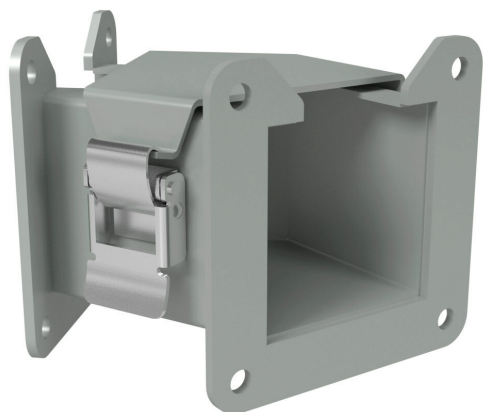

Hammond lay-in wireway fitting, 45-degree elbow, 2.5 x 2.5in, top opening, carbon steel, ANSI 61 gray, powder coat finish, quick-release clamps, NEMA 12. For use with 1485 series wireway.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/1485B4N>

Technical Specifications

| | |
|---------------------|-----------------|
| Brand | Hammond |
| Item | Wireway fitting |
| Fitting Type | 45-degree elbow |
| Wireway Type | Lay-in |
| Size | 2.5 x 2.5in |
| Opening | Top |
| Material | Carbon steel |
| Color | ANSI 61 gray |

| | |
|---------------------|--------------------------------|
| Finish | Powder coat |
| Cover Type | Hinged |
| Latch Type | Quick-release clamps |
| Knockouts | No |
| NEMA Rating | 12 |
| IP Rating | IP54 |
| Includes | (1) snap-on flat sealing plate |
| For Use With | 1485 series wireway |

Agency Approvals

| | |
|-----------------------------|---|
| UL Listed File # | E186830 |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CSA File # | LL21312 |
| RoHS Status | Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below) |
| EU REACH | View EU REACH document |
| Other | RoHS Statement |

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/1485B4N.pdf>
See store item page for other formats.