


# 1485C9Q Cut Sheet

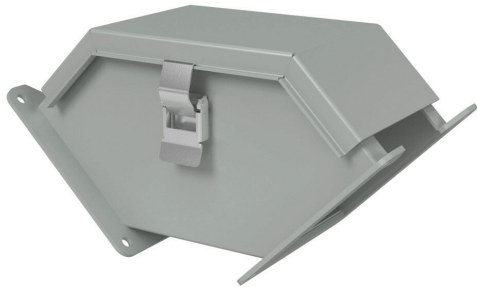

Hammond lay-in wireway fitting, 90-degree elbow, 4 x 4in, outside opening, carbon steel, ANSI 61 gray, powder coat finish, quick-release clamps, NEMA 12. For use with 1485 series wireway.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/1485C9Q>

## Technical Specifications

|                     |                 |
|---------------------|-----------------|
| <b>Brand</b>        | Hammond         |
| <b>Item</b>         | Wireway fitting |
| <b>Fitting Type</b> | 90-degree elbow |
| <b>Wireway Type</b> | Lay-in          |
| <b>Size</b>         | 4 x 4in         |
| <b>Opening</b>      | Outside         |
| <b>Material</b>     | Carbon steel    |
| <b>Color</b>        | ANSI 61 gray    |

|                     |                                |
|---------------------|--------------------------------|
| <b>Finish</b>       | Powder coat                    |
| <b>Cover Type</b>   | Hinged                         |
| <b>Latch Type</b>   | Quick-release clamps           |
| <b>Knockouts</b>    | No                             |
| <b>NEMA Rating</b>  | 12                             |
| <b>IP Rating</b>    | IP54                           |
| <b>Includes</b>     | (1) snap-on flat sealing plate |
| <b>For Use With</b> | 1485 series wireway            |

## Agency Approvals

|                             |   |
|-----------------------------|---|
| <b>UL Listed File #</b>     | E186830   |
| <b>UL Recognized File #</b> | None  |
| <b>UL Hazardous File #</b>  | None  |
| <b>CSA File #</b>           | LL21312   |
| <b>RoHS Status</b>          | Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below) |
| <b>EU REACH</b>             | <a href="#">View EU REACH document</a>                              |
| <b>Other</b>                | <a href="#">RoHS Statement</a>                                      |

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/1485C9Q.pdf>  
See store item page for other formats.