


1555VA2GY Cut Sheet

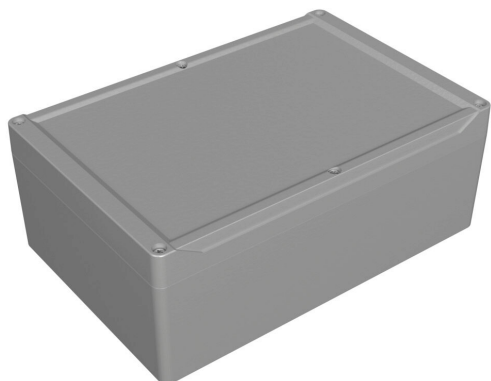

Hammond enclosure, NEMA 4/4X/6/6P/12/13, 240 x 160 x 90mm (HxWxD), polycarbonate, RAL 7035 light gray, screw cover with smooth recess, purchase subpanel separately.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/1555VA2GY>

Technical Specifications

| | |
|---------------------------------|--------------------------------|
| Brand | Hammond |
| Item | Enclosure |
| Subpanel | Purchase subpanel separately |
| NEMA Rating | 4/4X/6/6P/12/13 |
| IP Rating | IP68 |
| Enclosure Height | 240.00mm |
| Enclosure Width | 160.00mm |
| Enclosure Depth | 90.00mm |
| Cover Type | Screw cover with smooth recess |
| Cover Depth | 22mm |
| Integral Mounting Flange | No |
| Material | Polycarbonate |
| Color | RAL 7035 light gray |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | None |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CSA File # | None |
| RoHS Status | Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below) |
| EU REACH | View EU REACH document |
| Other | RoHS Statement |