


1602-5381 Cut Sheet

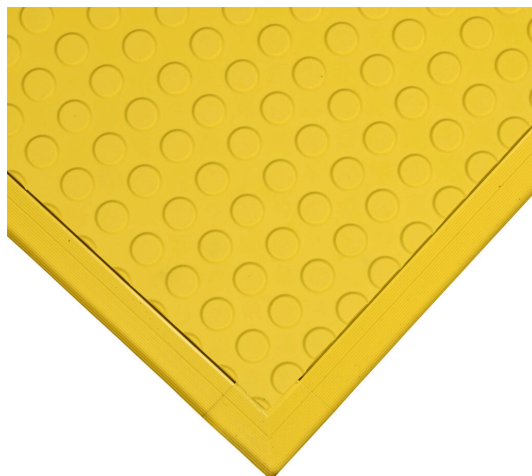

ASO Safety Solutions safety contact mat, 24 x 48in, integrated taper edge, 24 VAC/VDC operating voltage, polyurethane contact surface, yellow, IP65, 19.6ft/6m cable length, pigtail.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/1602-5381>

Technical Specifications

| | |
|-------------------------|----------------------|
| Brand | ASO Safety Solutions |
| Item | Safety contact mat |
| Size | 24 x 48in |
| Actuation Force | 150N |
| Response Time | < 25ms |
| Switching Cycles | > 1,000,000 cycles |
| Static Load | 2000N |
| Edge | Integrated taper |

| | |
|---------------------------------|--------------|
| Operating Voltage | 24 VAC/VDC |
| Contact Surface Material | Polyurethane |
| Color | Yellow |
| IP Rating | IP65 |
| Operating Temperature | -10 to 55C |
| Cable Length | 19.6ft/6m |
| Connection | Pigtail |
| Conductor Size | 22 AWG |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | E329422 |
| UL Recognized File # | N/A |
| UL Hazardous File # | N/A |
| CE | View CE declarations |
| CSA File # | N/A |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/1602-5381.pdf>
See store item page for other formats.