


203300000000011 Cut Sheet

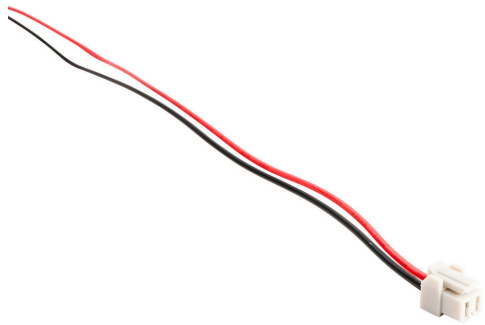

Mindman solenoid valve cable, JAM RMH male to pigtail, straight cable entry, 24 VDC, 24 AWG, 9.8ft/3m cable length. For use with MVDY-100 series miniature solenoid valves.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/203300000000011>

Technical Specifications

Brand	Mindman
Item	Cable
Cable Type	Solenoid valve
Connection 1	JAM RMH male
Connection 2	Pigtail
Cable Entry	Straight
Voltage Rating	24 VDC
Conductor Size	24 AWG
Cable Length	9.8ft/3m
For Use With	MVDY-100 series miniature solenoid valves

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/203300000000011.pdf>
See store item page for other formats.