


21565157055 Cut Sheet

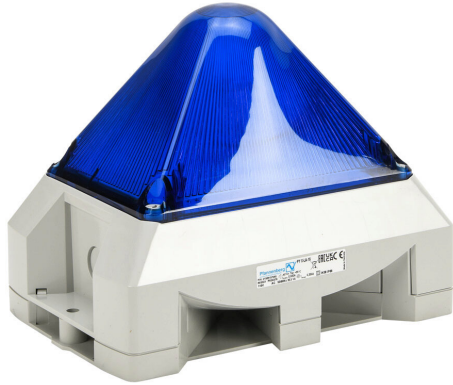

Pfannenberg PYRA series Xenon tube audible-visual signal beacon, 103 dB at 1m, (8) selectable tone(s), selectable flashing strobe, blue, 216 x 144 x 172mm, 115 VAC, IP66, NEMA 4/4X.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/21565157055>

Technical Specifications

Brand	Pfannenberg
Item	Audible-visual signal beacon
Series	PYRA
Bulb Type	Xenon tube
Operator Size	216 x 144 x 172mm
Operator Color	Blue
Light Color(s)	Blue
Light Function	Selectable flashing strobe
Housing Material	Polycarbonate
Material	ABS plastic

Loudness Decibel	103 dB at 1m
Tone Frequency	110 Hz to 3 kHz
Tone Type	(8) selectable
Touch to Acknowledge	No
Number of Alarms	8
Voltage Rating	115 VAC
Mounting	Surface
IP Rating	IP66
NEMA Rating	4/4X
Connection	Screw terminal

Agency Approvals

UL Listed File #	S7256
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/21565157055.pdf>
See store item page for other formats.