


21565807055 Cut Sheet

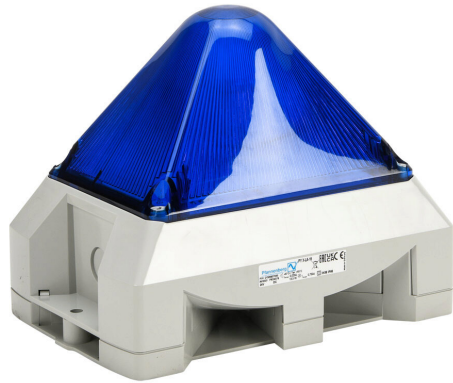

Pfannenberg PYRA series Xenon tube audible-visual signal beacon, 103 dB at 1m, (8) selectable tone(s), selectable flashing strobe, blue, 216 x 144 x 172mm, 24 VDC, IP66, NEMA 4/4X.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/21565807055>

Technical Specifications

Brand	Pfannenberg	Material	ABS plastic
Item	Audible-visual signal beacon	Loudness Decibel	103 dB at 1m
Series	PYRA	Tone Frequency	110 Hz to 3 kHz
Bulb Type	Xenon tube	Tone Type	(8) selectable
Operator Size	216 x 144 x 172mm	Touch to Acknowledge	No
Operator Color	Blue	Voltage Rating	24 VDC
Light Color(s)	Blue	Mounting	Surface
Light Function	Selectable flashing strobe	IP Rating	IP66
Housing Material	Polycarbonate	NEMA Rating	4/4X

Agency Approvals

UL Listed File #	S7256
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/21565807055.pdf>
See store item page for other formats.