


21WN4K1E130-T5-A Cutsheet



ODE potable water solenoid valve, 2-port (2-way), 2-position, N.C., lead-free brass body, 1/2in female NPT inlet(s), 1/2in female NPT outlet(s), Cv=4.8, 120 VAC (60Hz)/110 VAC (50Hz) operating voltage, 15 VA, NSF/ANSI 61.

For complete product information, please see this item on our store at the following link:

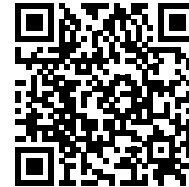

<https://www.automationdirect.com/pn/21WN4K1E130-T5-A>

Technical Specifications

Brand	ODE
Item	Valve
Working Fluid	Potable water
Valve Type	Solenoid process
Agency Approval	NSF/ANSI 61
Port Quantity	2-port (2-way)
Number Of Positions	2
Valve Configuration	N.C.
Action	Single solenoid spring return
Body Material	Lead-free brass
Inlet Port	1/2in female NPT
Outlet Port	1/2in female NPT
Flow Coefficient	4.8
Minimum Operating Pressure	2.9 psi
Maximum Operating Pressure	232 psi
Operating Voltage	120 VAC (60Hz)/110 VAC (50Hz)
Power Rating	15 VA
Electrical Connection	18mm DIN style wiring plug
Additional Information	Valve part number

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document
Other	None