


# 267071 Cut Sheet

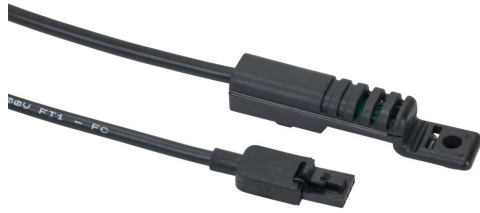

Stego temperature/humidity sensor, -4 to 104 deg F, 40 to 90% RH, 35mm DIN rail mount, 3.2ft/1m cable length. For use with Stego 0309xx-17 & 1309xx-17 heaters.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/267071>

## Technical Specifications

<b>Brand</b>	Stego
<b>Item</b>	Temperature/humidity sensor
<b>Temperature Sensing Range</b>	-4 to 104 deg F
<b>Humidity Sensing Range</b>	40 to 90% RH
<b>Mounting</b>	35mm DIN rail
<b>Cable Length</b>	3.2ft/1m
<b>For Use With</b>	Stego 0309xx-17 & 1309xx-17 heaters

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	E234324
<b>UL Hazardous File #</b>	None
<b>CSA File #</b>	None
<b>RoHS Status</b>	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	<a href="#">RoHS Statement</a>