


280MXL025NG Cut Sheet

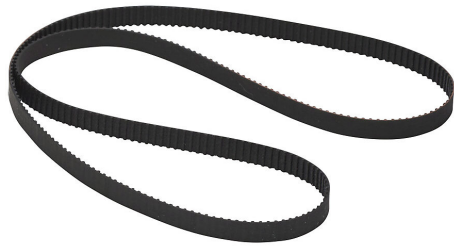

SureMotion timing belt, 0.08in MXL pitch, 1/4in wide, 280 tooth, 22.4in pitch length (circumference), neoprene, fiberglass reinforced. Package of 3.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/280MXL025NG>

Technical Specifications

| | |
|----------------------------|-------------|
| Brand | SureMotion |
| Item | Timing belt |
| Pitch | 0.08in MXL |
| Width | 1/4in |
| Number of Teeth | 280 |
| Pitch length | 22.4in |
| Material | Neoprene |
| Reinforcement | Fiberglass |
| Belt Tensile Rating | 103lb |
| Quantity per Pack | 3 |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | None |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | None |
| CSA File # | None |
| RoHS Status | No |
| EU REACH | View EU REACH document |