


38616005 Cut Sheet

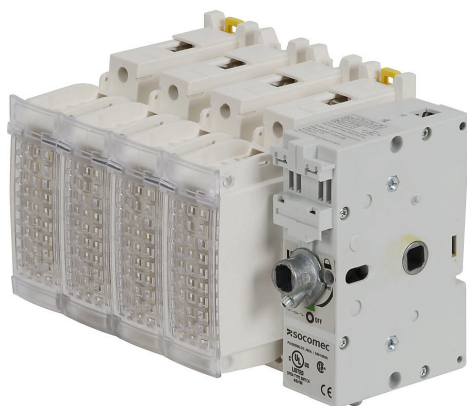

Socomec FUSERBLOC series rotary disconnect switch, fusible, Class J, load break capable, 4-pole, 600 VAC/250 VDC, 60A, 100kA SCCR, DIN rail or panel mount, UL 98 rated, front or side operated, accepts 10 x 10mm size shaft.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/38616005>

Technical Specifications

Brand	Socomec
Item	Disconnect switch
Series	FUSERBLOC
Fuse Class	Class J
Fusible	Yes
Load Break Capable	Yes
Number of Poles	4
Voltage Rating	600 VAC/250 VDC
Amperage Rating	60A
SCCR Rating	100kA SCCR
Mounting	DIN rail or panel
UL Rating	UL 98 rated
Configuration	Front or side operated
Shaft Size	Accepts 10 x 10mm size shaft
Handle Type	Rotary
Additional Information	Purchase fuses and handle separately

Agency Approvals

UL Listed File #	E201138
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	112964
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document