


3UHD7211918N4SS Cut Sheet

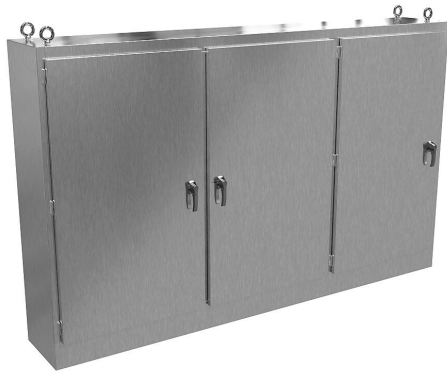

Hammond disconnect enclosure, NEMA 3R/4/4X/12/13, right flange, 72 x 119 x 18in (HxWxD), freestanding, 304 stainless steel, #4 brush finish, 3-door, 3-point padlocking handle.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/3UHD7211918N4SS>

Technical Specifications

Brand	Hammond
Item	Disconnect enclosure
Slope Top	No
NEMA Rating	3R/4/4X/12/13
IP Rating	IP66
Disconnect Mounting	Right flange
Nominal Enclosure Dimensions	72 x 119 x 18in (HxWxD)
Enclosure Height	72.13in
Enclosure Width	118.25in
Enclosure Depth	19.35in
Mounting	Freestanding
Dual Access	No

Knockouts	No
Material	304 stainless steel
Finish	#4 brush
Cover Type	3-door
Hinge Type	Lift-off hinges
Number of Hinges Per Door	3
Latch Type	3-point padlocking handle
Padlockable	Yes
Subpanel	(2) subpanels included
Additional Information	Purchase operating mechanism, disconnect switch or circuit breaker, and operating handle from disconnect supplier

Agency Approvals

UL Listed File #	E65324
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	LR21001
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/3UHD7211918N4SS.pdf>
See store item page for other formats.