


3UHD8411924N4SS Cut Sheet



Hammond disconnect enclosure, NEMA 3R/4/4X/12/13, right flange, 84 x 119 x 24in (HxWxD), freestanding, 304 stainless steel, #4 brush finish, 3-door, 3-point padlocking handle.

For complete product information, please see this item on our store at the following link:

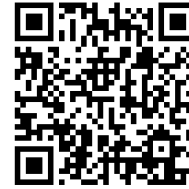

<https://www.automationdirect.com/pn/3UHD8411924N4SS>

Technical Specifications

Brand	Hammond	Knockouts	No
Item	Disconnect enclosure	Material	304 stainless steel
Slope Top	No	Finish	#4 brush
NEMA Rating	3R/4/4X/12/13	Cover Type	3-door
IP Rating	IP66	Hinge Type	Lift-off hinges
Disconnect Mounting	Right flange	Number of Hinges Per Door	3
Nominal Enclosure Dimensions	84 x 119 x 24in (HxWxD)	Latch Type	3-point padlocking handle
Enclosure Height	84.13in	Padlockable	Yes
Enclosure Width	118.25in	Subpanel	(2) subpanels included
Enclosure Depth	25.35in	Additional Information	Purchase operating mechanism, disconnect switch or circuit breaker, and operating handle from disconnect supplier
Mounting	Freestanding		
Dual Access	No		

Agency Approvals

UL Listed File #	E65324
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	LR21001
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document