


# 4002 Cut Sheet

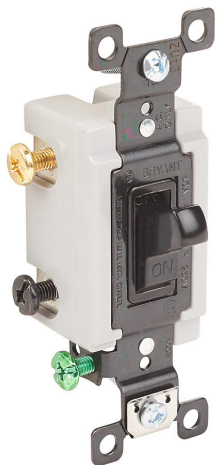

Bryant manual motor controller, open, 40A, 600 VAC, 2-pole, 5hp.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/4002>

## Technical Specifications

Brand	Bryant
Item	Manual motor controller
Body Type	Open
Amperage Rating	40A
Voltage Rating	600 VAC
Number of Poles	2
Horsepower Rating	5hp
Wiring Type	Can be wired from the side only
Additional Information	Not suitable as motor disconnect per UL 508

## Agency Approvals

UL Listed File #	None
UL Recognized File #	E70402
UL Hazardous File #	None
CE	None
CSA File #	46186
RoHS Status	No
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/4002.pdf>  
See store item page for other formats.