


# 41502012 Cut Sheet

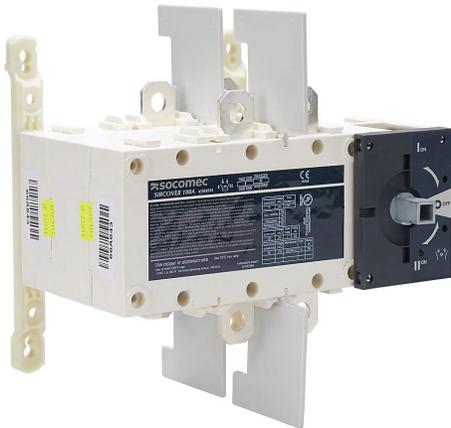

Socomec SIRCOVER series rotary manual transfer switch, 2-pole, 240 VAC, 100A, 100kA SCCR, panel mount, UL1008 rated, front operated, accepts 10 x 10mm size shaft.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/41502012>

## Technical Specifications

<b>Brand</b>	Socomec
<b>Item</b>	Manual transfer switch
<b>Series</b>	SIRCOVER
<b>Fusible</b>	No
<b>Load Break Capable</b>	No
<b>Number of Poles</b>	2
<b>Voltage Rating</b>	240 VAC
<b>Amperage Rating</b>	100A

<b>SCCR Rating</b>	100kA SCCR
<b>Mounting</b>	Panel
<b>UL Rating</b>	UL1008 rated
<b>Configuration</b>	Front operated
<b>Shaft Size</b>	Accepts 10 x 10mm size shaft
<b>Handle Type</b>	Rotary
<b>Additional Information</b>	Purchase handle separately. Line & load terminal screens, lugs, and bridging bars sold separately

## Agency Approvals

<b>UL Listed File #</b>	E173959
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/41502012.pdf>  
See store item page for other formats.