


# 4MB-4FB90 Cut Sheet

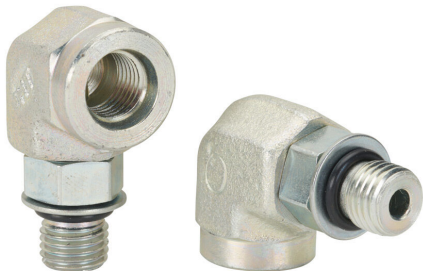

HY-TECH hydraulic fluid adapter, elbow, plated steel body, (1) -4 male o-ring boss and (1) -4 female o-ring boss. Package of 2.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/4MB-4FB90>

## Technical Specifications

|                   |  |
|-------------------|--|
| Brand             | HY-TECH  |
| Item              | Adapter  |
| Working Fluid     | Hydraulic fluid  |
| Adapter Type      | Elbow  |
| Body Material     | Plated steel   |
| Thread Material   | Plated steel   |
| Measurement Type  | SAE  |
| Connection        | (1) -4 male o-ring boss and<br>(1) -4 female o-ring boss |
| Quantity per Pack | 2  |

## Agency Approvals

|                      |  |
|----------------------|--|
| UL Listed File #     | None                                   |
| UL Recognized File # | None                                   |
| UL Hazardous File #  | None                                   |
| CE                   | None                                   |
| CSA File #           | None                                   |
| RoHS Status          | No                                     |
| EU REACH             | <a href="#">View EU REACH document</a> |