


50020851106114 Cut Sheet

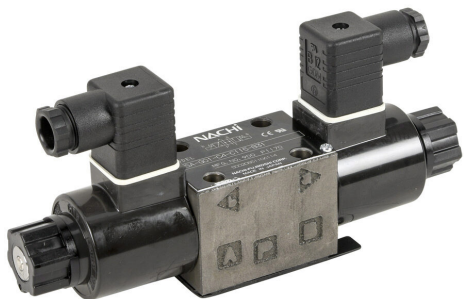

Bucher hydraulic solenoid valve, D03, 4-port (4-way), 3-position, center open, double solenoid, cast iron body, momentary manual override, 13.2 GPM, 120 VAC, 27W, 18mm DIN style wiring plug.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/50020851106114>

Technical Specifications

Brand	Bucher
Item	Valve
Working Fluid	Petroleum based hydraulic fluid
Valve Type	Solenoid directional control
Port Quantity	4-port (4-way)
Number Of Positions	3
Valve Configuration	Center open
Action	Double solenoid
Body Material	Cast iron
Seal Material	Nitrile
Manual Override Type	Momentary

Flow Capacity	13.2 GPM
Maximum Operating Pressure	5075 psi
Minimum Operating Pressure	0 psi
Working Fluid Temperature	10-170 °F
Operating Voltage	120 VAC
Power Rating	27W
Electrical Connection	18mm DIN style wiring plug
Form Factor	D03
Includes	Mounting hardware
Manufacturer Part Number	11061-N

Agency Approvals

RoHS Status	No
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/50020851106114.pdf>
See store item page for other formats.