


500KC114B-10 Cut Sheet

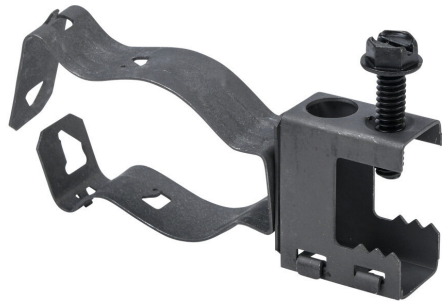

Minerallac screw-on beam clamp conduit hanger assembly, spring clip, back mount, 100 lbs. Package of 10. For use with flanges up to 1/2in and 1-1/4in conduit.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/500KC114B-10>

Technical Specifications

Brand	Minerallac
Item	Conduit hanger assembly
Mount Type	Screw-on beam clamp
Hanger Type	Spring clip
Mount Side	Back
Material	Spring steel
Finish	Zinc phosphate plated
Mounting Holes	1/4-20 UNC bottom and 3/8in pass through bottom
Maximum Flange Thickness	1/2in
Set Screw Size	1/4in-20 UNC
Load Rating	100 lbs
Outside Diameter	1.51in-1.66in

Rigid Metallic Conduit (RMC) Trade Size	1-1/4in
Electrical Metallic Tubing (EMT) Trade Size	1-1/4in
Intermediate Metallic Conduit (IMC) Trade Size	1-1/4in
Reduced Wall Flexible Metal Conduit Trade Size	1-1/4in
Liquid-tight Flexible Metal Conduit (LFMC) Trade Size	1-1/4in
Quantity per Pack	10
For Use With	Flanges up to 1/2in and 1-1/4in conduit

Agency Approvals

CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document