


# 7000-12021-2141000 Cut Sheet

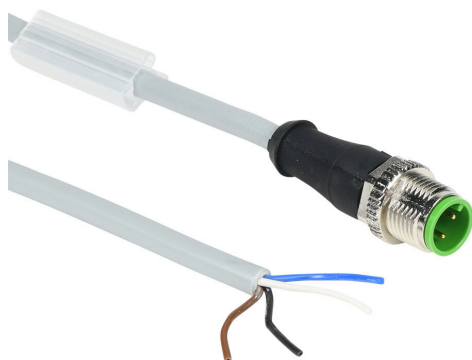

Murrelektronik connection cable, M12 axial male A-coded to pigtail, 4-pole, 250 VAC/VDC, 4A, 22 AWG, PVC jacket, gray, unshielded, 32.8ft/10m cable length, IP65 IP66K IP67, sensor & signal.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/7000-12021-2141000>

## Technical Specifications

Brand	Murrelektronik
Item	Cable
Cable Type	Connection
Connection 1	M12 axial male with male threads A-coded
Connection 2	Pigtail
Number of Poles	4
Voltage Rating	250 VAC/VDC
Amperage Rating	4A

Conductor Size	22 AWG
Jacket Material	PVC
Jacket Color	Gray
Shield Type	Unshielded
Cable Length	32.8ft/10m
IP Rating	IP65 IP66K IP67
Application	Sensor & signal

## Agency Approvals

UL Listed File #	E325311
UL Recognized File #	n/a
CE	<a href="#">View CE declarations</a>
CSA File #	080128-0-000
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/7000-12021-2141000.pdf>  
See store item page for other formats.