


# 7000-74001-0000000 Cut Sheet

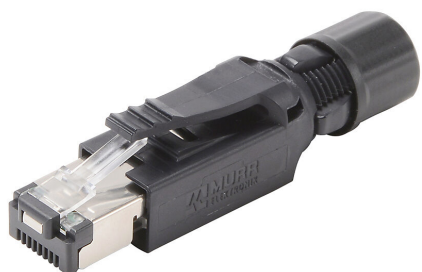

Murrelektronik Cat5e Ethernet connector, field-wireable, RJ45 4-pole Ethernet male axial, accepts cable diameter size 4.5-9mm, 26-22 AWG, insulation displacement (IDC) connection, IP20.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/7000-74001-0000000>

## Technical Specifications

Brand	Murrelektronik
Item	Connector
Field-Wireable	Yes
Form Factor	Cable termination
Connector Standard	Cat5e Ethernet
Connector Type	RJ45
Gender	Male
Angle	Axial

Number of Pins	8
Terminal Connection	Insulation displacement (IDC)
Cable Diameter Size	4.5-9mm
Conductor Size	26-22 AWG
Shielded	Yes
Housing Material	PVC/polyethylene
IP Rating	IP20
Additional Information	Exceeds Category 5E specifications

## Agency Approvals

UL Listed File #	None
UL Recognized File #	E224242
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	<a href="#">View EU REACH document</a>
Other	<a href="#">RoHS Statement</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/7000-74001-0000000.pdf>  
See store item page for other formats.