


# 7024-12321-3150500 Cut Sheet

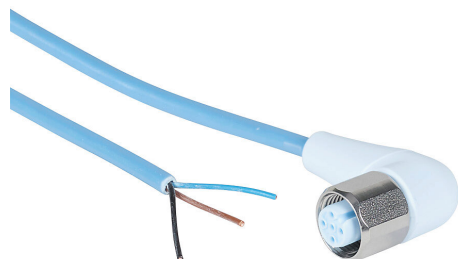

Murrelektronik connection cable, M12 right-angle female to pigtail, 3-pole, styrene-butadiene thermoplastic (TPE-S) jacket, ice blue, 16.4ft/5m cable length, IP65, IP68 and IP69K, sensor & signal.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/7024-12321-3150500>

## Technical Specifications

<b>Brand</b>	Murrelektronik
<b>Item</b>	Cable
<b>Cable Type</b>	Connection
<b>Connection 1</b>	M12 right-angle female
<b>Connection 2</b>	Pigtail
<b>Number of Poles</b>	3
<b>Jacket Material</b>	Styrene-butadiene thermoplastic (TPE-S)

<b>Jacket Color</b>	Ice blue
<b>Cable Length</b>	16.4ft/5m
<b>IP Rating</b>	IP65, IP68 and IP69K
<b>Application</b>	Sensor & signal
<b>Additional Information</b>	Suitable for food and beverage applications, FDA compliant

## Agency Approvals

<b>UL Listed File #</b>	E325311
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	080128_0_000
<b>RoHS Status</b>	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	<a href="#">RoHS Statement</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/7024-12321-3150500.pdf>  
See store item page for other formats.