


7024-12341-3212000 Cut Sheet

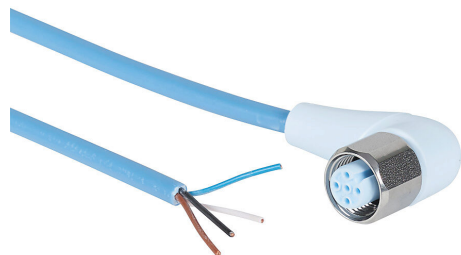

Murrelektronik connection cable, M12 right-angle female to pigtail, 4-pole, styrene-butadiene thermoplastic (TPE-S) jacket, ice blue, 65.6ft/20m cable length, IP65, IP68 and IP69K, suitable for food and beverage applications, FDA compliant.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/7024-12341-3212000>

Technical Specifications

| | |
|------------------------|--|
| Brand | Murrelektronik |
| Item | Cable |
| Cable Type | Connection |
| Connection 1 | M12 right-angle female |
| Connection 2 | Pigtail |
| Number of Poles | 4 |
| Jacket Material | Styrene-butadiene thermoplastic (TPE-S) |
| Jacket Color | Ice blue |
| Cable Length | 65.6ft/20m |
| IP Rating | IP65, IP68 and IP69K |
| Application | Suitable for food and beverage applications, FDA compliant |

Agency Approvals

| | |
|-----------------------------|---|
| UL Listed File # | E325311 |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | None |
| CSA File # | 080128_0_000 |
| RoHS Status | Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below) |
| EU REACH | View EU REACH document |
| Other | RoHS Statement |