


7024-17141-4060150 Cut Sheet

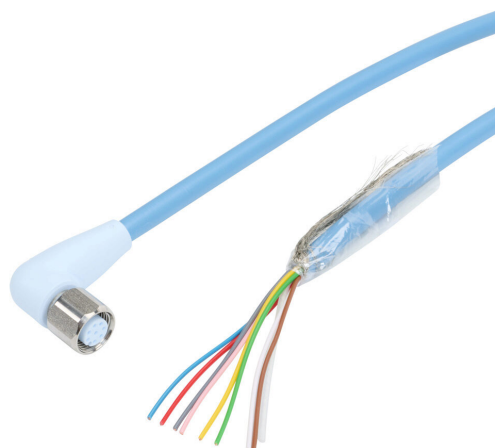

Murrelektronik connection cable, M12 right-angle female to pigtail, 8-pole, 30 VAC/VDC, 2.0A, 24 AWG, styrene-butadiene thermoplastic (TPE-S) jacket, ice blue, shielded, 4.9ft/1.5m cable length, IP65, IP68 and IP69K, sensor & signal and drag chain.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/7024-17141-4060150>

Technical Specifications

Brand	Murrelektronik
Item	Cable
Cable Type	Connection
Connection 1	M12 right-angle female
Connection 2	Pigtail
Number of Poles	8
Voltage Rating	30 VAC/VDC
Amperage Rating	2.0A
Conductor Size	24 AWG

Jacket Material	Styrene-butadiene thermoplastic (TPE-S)
Jacket Color	Ice blue
Shield Type	Overall aluminum foil and tinned copper braid
Cable Length	4.9ft/1.5m
IP Rating	IP65, IP68 and IP69K
Application	Sensor & signal and drag chain
Additional Information	Suitable for food and beverage applications, FDA compliant

Agency Approvals

UL Listed File #	E325311
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/7024-17141-4060150.pdf>
See store item page for other formats.