


71520NP Cut Sheet



Bryant industrial heavy duty locking blade plug, 20A, 250 VAC, 3-phase, 3-pole, 4-wire, NEMA L15-20, accepts cord size 0.46-1.15in, nylon housing, black and white.

For complete product information, please see this item on our store at the following link:

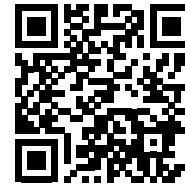

<https://www.automationdirect.com/pn/71520NP>

Technical Specifications

Brand	Bryant
Item	Plug
Application	Industrial heavy duty
Blade Type	Locking
With Cap	No
Self-grounding	No
Amperage Rating	20A
Voltage Rating	250 VAC
Number of Phases	3
Number of Poles	3
Number of Wires	4
Wire Size	18-8 AWG
Copper Wire Only	No
Configuration	NEMA L15-20
Cord Diameter	0.46-1.15in
Housing Material	Nylon
Color	Black and white

Agency Approvals

UL Listed File #	E1381
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	016215
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document
Other	None