


7700-P4201-U0D1000 Cut Sheet

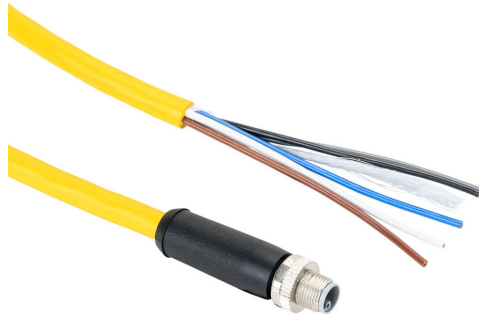

Murrelektronik power cable, M12 axial male L-coded to pigtail, 5-pole, 63 VDC, 12A, 16 AWG, TPE jacket, yellow, 32.8ft/10m cable length, IP65 IP67.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/7700-P4201-U0D1000>

Technical Specifications

Brand	Murrelektronik
Item	Cable
Cable Type	Power
Connection 1	M12 axial male L-coded
Connection 2	Pigtail
Number of Poles	5
Voltage Rating	63 VDC
Amperage Rating	12A
Conductor Size	16 AWG
Jacket Material	TPE
Jacket Color	Yellow
Cable Length	32.8ft/10m
IP Rating	IP65 IP67

Agency Approvals

UL Listed File #	E492831
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/7700-P4201-U0D1000.pdf>
See store item page for other formats.