


# 7700-P4221-U0D0750 Cut Sheet

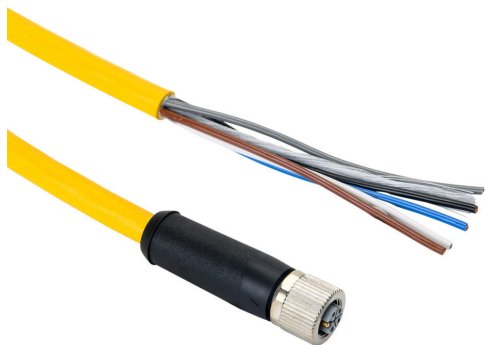

Murrelektronik power cable, M12 axial female L-coded to pigtail, 5-pole, 63 VDC, 12A, 16 AWG, TPE jacket, yellow, 24.6ft/7.5m cable length, IP65 IP67.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/7700-P4221-U0D0750>

## Technical Specifications

Brand	Murrelektronik
Item	Cable
Cable Type	Power
Connection 1	M12 axial female L-coded
Connection 2	Pigtail
Number of Poles	5
Voltage Rating	63 VDC
Amperage Rating	12A
Conductor Size	16 AWG
Jacket Material	TPE
Jacket Color	Yellow
Cable Length	24.6ft/7.5m
IP Rating	IP65 IP67

## Agency Approvals

UL Listed File #	E492831
UL Recognized File #	None
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/7700-P4221-U0D0750.pdf>  
See store item page for other formats.