


# 857-400 Cut Sheet

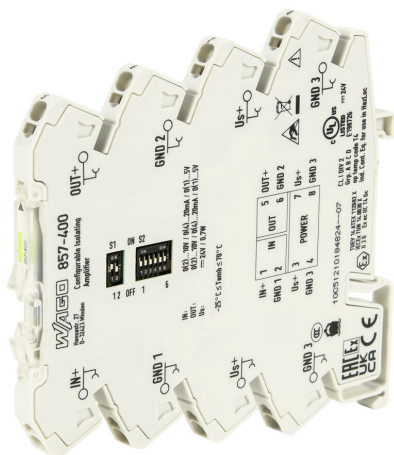

WAGO signal conditioner, isolated, Input: 1-channel, current/voltage, Output: 1-channel, current/voltage, 24 VDC operating voltage, 35mm DIN rail mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/857-400>

## Technical Specifications

Brand	WAGO
Item	Signal conditioner
Isolation	Isolated
Field Configurable	Yes
Number Of Input Channels	1
Input	Current/voltage
Input Current Signal Range	0-20 mA and 4-20 mA
Input Voltage Signal Range	0-5 VDC, 1-5 VDC, 0-10 VDC and 2-10 VDC
Number Of Output Channels	1

Output	Current/voltage
Output Current Signal Range	0-20 mA and 4-20 mA
Output Voltage Signal Range	0-5 VDC, 1-5 VDC, 0-10 VDC and 2-10 VDC
Operating Voltage	24 VDC
Housing Material	Plastic
Mounting	35mm DIN rail
Electrical Connection	Push-in terminals
Application	Hazardous location rated

## Agency Approvals

UL Listed File #	E175199
UL Recognized File #	None
UL Hazardous File #	E198726
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/857-400.pdf>  
See store item page for other formats.