


857-423 Cut Sheet

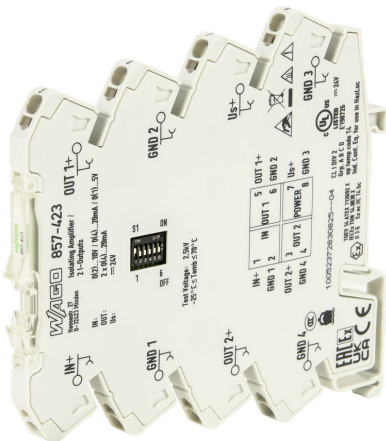

WAGO signal conditioner, isolated, Input: 1-channel, current/voltage, Output: 2-channel, current, 24 VDC operating voltage, 35mm DIN rail mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/857-423>

Technical Specifications

Brand	WAGO
Item	Signal conditioner
Isolation	Isolated
Field Configurable	Yes
Number Of Input Channels	1
Input	Current/voltage
Input Current Signal Range	0-20 mA and 4-20 mA
Input Voltage Signal Range	0-5 VDC, 1-5 VDC, 0-10 VDC and 2-10 VDC
Number Of Output Channels	2

Output	Current
Output Current Signal Range	0-20 mA and 4-20 mA
Output Current Signal Range 2	0-20 mA and 4-20 mA
Operating Voltage	24 VDC
Housing Material	Plastic
Mounting	35mm DIN rail
Electrical Connection	Push-in terminals
Application	Hazardous location rated

Agency Approvals

UL Listed File #	E175199
UL Recognized File #	None
UL Hazardous File #	E198726
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/857-423.pdf>
See store item page for other formats.