


857-452 Cut Sheet

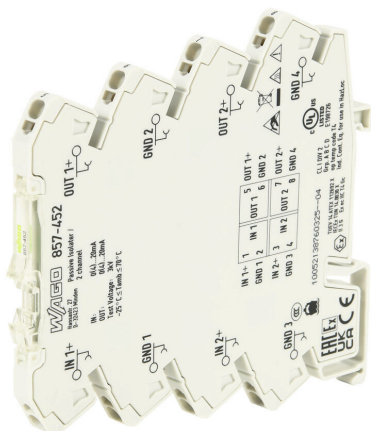

WAGO signal conditioner, isolated, Input: 2-channel, loop powered current, Output: 2-channel, current, 35mm DIN rail mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/857-452>

Technical Specifications

Brand	WAGO
Item	Signal conditioner
Isolation	Isolated
Field Configurable	No
Number Of Input Channels	2
Input	Loop powered current
Input Current Signal Range	0-20 mA and 4-20 mA
Input Current Signal Range 2	0-20 mA and 4-20 mA

Number Of Output Channels	2
Output	Current
Output Current Signal Range	0-20 mA and 4-20 mA
Output Current Signal Range 2	0-20 mA and 4-20 mA
Housing Material	Plastic
Mounting	35mm DIN rail
Electrical Connection	Push-in terminals
Application	Hazardous location rated

Agency Approvals

UL Listed File #	E175199
UL Recognized File #	None
UL Hazardous File #	E198726
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/857-452.pdf>
See store item page for other formats.