


859-801 Cut Sheet

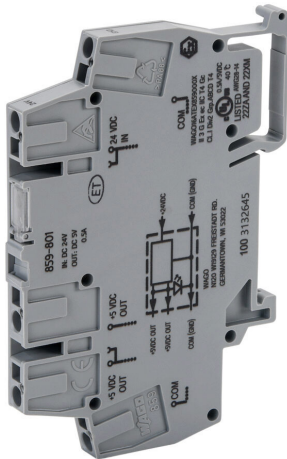

WAGO DC to DC converter, 10-30 VDC input, 5 VDC output, 0.5A, 2.5W, plastic housing, 35mm DIN rail mount, cage clamp.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/859-801>

Technical Specifications

| | |
|-----------------------------|--------------------|
| Brand | WAGO |
| Item | DC to DC converter |
| Input voltage range | 10-30 VDC |
| Output Voltage Range | 5 VDC |
| Load Current | 0.5A |
| Output Power | 2.5W |
| Housing Material | Plastic |
| Encapsulated | No |
| Mounting | 35mm DIN rail |
| Terminal Block Type | Cage clamp |
| Removable | No |

Agency Approvals

| | |
|----------------------------|--|
| UL Listed File # | E175199 |
| UL Hazardous File # | None |
| CE | View CE declarations |
| CSA File # | None |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/859-801.pdf>
See store item page for other formats.