


927944 Cut Sheet

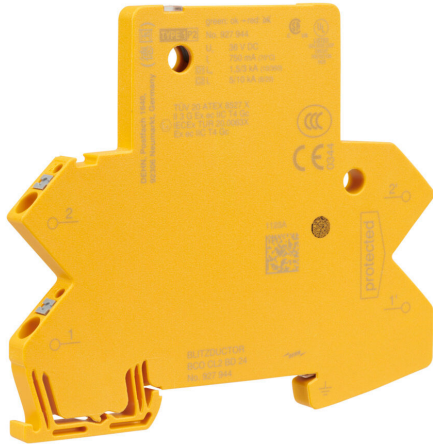

Dehn BCO compact series data & signal Surge Protective Device (SPD), 5 kA discharge current, 24 VAC/VDC, series circuit, indirect grounding, 2 lines or 1 pair, 35mm DIN rail mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/927944>

Technical Specifications

Brand	Dehn
Item	Surge Protective Device (SPD)
Series	BCO compact
Surge Protection Type	Data & signal protection
Signal Types Protected	0-20mA, 4-20mA, Fieldbus systems, digital signals
Circuit Type	Series circuit
Grounding Type	Indirect
Channels	2 lines or 1 pair
Neutral Ground Protection	No

System Voltage	24 VAC/VDC
Nominal Discharge Current	5 kA
Voltage Protection Rating (VPR)	57V (L-L), 600V (L-G)
UL Rating	UL 497B rated
Mounting	35mm DIN rail
Connection	Spring terminals
Additional Information	Integral life status function, requires monitoring module 910710 sold separately

Agency Approvals

UL Listed File #	E156818 Displayed as BCO CL2 BD 24
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	80066004 Displayed as BCO CL2 BD 24
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/927944.pdf>
See store item page for other formats.