


929970 Cut Sheet

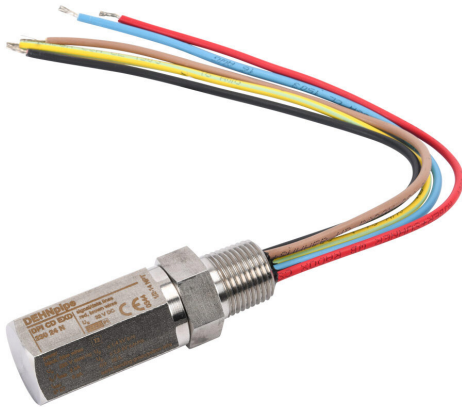

Dehn DPI-CD series power, data & signal Surge Protective Device (SPD), 230/120 VAC 1-Phase & 24V, parallel circuit, 2 lines or 1 pair, IP67, 1/2in-14 NPSM mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/929970>

Technical Specifications

Brand	Dehn
Item	Surge Protective Device (SPD)
Series	DPI-CD
Surge Protection Type	Power, data & signal protection
Signal Types Protected	0-20mA, 4-20mA, Fieldbus systems
Circuit Type	Parallel circuit
Channels	2 lines or 1 pair
Neutral Ground Protection	No
System Voltage	230/120 VAC 1-Phase & 24V
Voltage Protection Rating (VPR)	58V (L-L), 900V (L-G)
Housing Material	Stainless steel
IP Rating	IP67
Mounting	1/2in-14 NPSM
Connection	5-wire 16 AWG pigtail
Application	Hazardous location rated

Agency Approvals

UL Listed File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	215727
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document