


950221 Cut Sheet

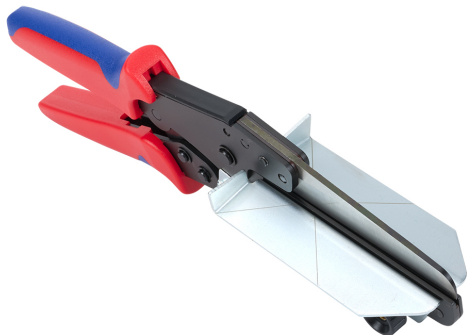

KNIPEX duct cutters, 8.3in (211mm) overall length, special steel hardened cutting edges, multi-component soft grip handle, locking mechanism for blade protection.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/950221>

Technical Specifications

Brand	KNIPEX
Item	Duct cutters
Overall Length	8.3in (211mm)
Insulated	No
Cutting	Special steel hardened cutting edges
Capacity	5/32in (4.0mm) thick plastic
Handle Type	Multi-component soft grip handle
Application	Duct cutting
Material	Vanadium steel, oil-hardened
Tool Features	Locking mechanism for blade protection
Additional Information	For cutting and shortening plastic cable ducts and other plastic materials

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement