


A1021603-1 Cut Sheet

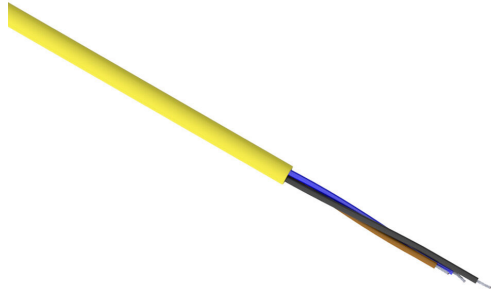

LUTZE IO-Link flexible control cable, unshielded, 3 conductors, 16 AWG, bare copper, PVC/Nylon conductor insulation material, black, brown and blue, PVC jacket, yellow, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A1021603-1>

Technical Specifications

Brand	LUTZE
Item	Cable
Series	IO-Link
Protocol	IO-Link
Wire/Cable Type	Control
UL Wire/Cable Type	TC-ER-JP, WTTTC and MTW
Applicable Standards	UL 20886
Application	IO-Link
Flexibility	Flexible
Voltage Rating	600V (Types TC, TC-ER, MTW), 1000V (Type WTTTC)
Conductors	3 conductors
Conductor Size	16 AWG
Conductor Stranding	26-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC/Nylon

Conductor Insulation Color	Black, brown and blue
Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Yellow
Nominal Overall Cable Diameter	0.321in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 1 to 50ft = Coil• 51 to 99ft = 14 x 7in Reel• 100 to 430ft = 14 x 10in Reel• 431 to 610ft = 16 x 10in Reel• 611 to 950ft = 18 x 10in Reel• 951 to 1340ft = 18 x 13in Reel• 1341 to 1750ft = 24 x 17in Wooden Reel• 1751 to 2500ft = 30 x 17in Wooden Reel

Agency Approvals

UL Listed File #	E324458
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document