


A1021605-1 Cut Sheet

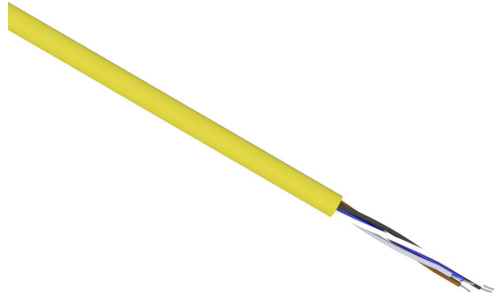

LUTZE IO-Link flexible control cable, unshielded, 5 conductors, 16 AWG, bare copper, PVC/Nylon conductor insulation material, black, brown, blue, white and gray, PVC jacket, yellow, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A1021605-1>

Technical Specifications

Brand	LUTZE	Conductor Insulation Color	Black, brown, blue, white and gray
Item	Cable	Shielding	Unshielded
Series	IO-Link	Jacket Material	PVC
Protocol	IO-Link	Jacket Color	Yellow
Wire/Cable Type	Control	Nominal Overall Cable Diameter	0.375in
UL Wire/Cable Type	TC-ER-JP, WTTTC and MTW	Bulk Length	Cut to length
Applicable Standards	UL 20886	Package Type	1 to 75ft = Coil, 76 to 275ft = 14 x 7in Reel, 276 to 395ft = 14 x 10in Reel, 396 to 605ft = 16 x 10in Reel, 606 to 850ft = 18 x 10in Reel, 851 to 1105ft = 18 x 13in Reel, 1106 to 2470ft = 24 x 17in Wooden Reel, 2471 to 2500ft = 30 x 17in Wooden Reel
Application	IO-Link		
Flexibility	Flexible		
Voltage Rating	600V (Types TC, TC-ER, MTW), 1000V (Type WTTTC)		
Conductors	5 conductors		
Conductor Size	16 AWG		
Conductor Stranding	26-stranded		
Conductor Material	Bare copper		
Conductor Insulation Material	PVC/Nylon		

Agency Approvals

UL Listed File #	E324458
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document