


A1022004-1 Cut Sheet

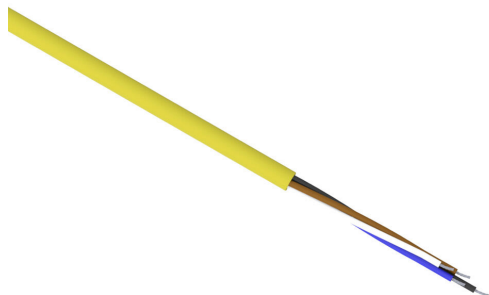

LUTZE IO-Link flexible control cable, unshielded, 4 conductors, 20 AWG, bare copper, PVC/Nylon conductor insulation material, black, brown, blue and white, PVC jacket, yellow, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A1022004-1>

Technical Specifications

Brand	LUTZE
Item	Cable
Series	IO-Link
Protocol	IO-Link
Wire/Cable Type	Control
UL Wire/Cable Type	PLTC-ER, ITC-ER and MTW
Applicable Standards	UL 20886
Application	IO-Link
Flexibility	Flexible
Voltage Rating	300V (Types PLTC-ER, ITC-ER), 600V (Type MTW)
Conductors	4 conductors
Conductor Size	20 AWG
Conductor Stranding	10-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC/Nylon

Conductor Insulation Color	Black, brown, blue and white
Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Yellow
Nominal Overall Cable Diameter	0.292in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 99ft = Coil• 100 to 455ft = 14 x 7in Reel• 456 to 655ft = 14 x 10in Reel• 656 to 1000ft = 16 x 10in Reel• 1001 to 1400ft = 18 x 10in Reel• 1401 to 1820ft = 18 x 13in Reel• 1821 to 2500ft = 24 x 17in Wooden Reel

Agency Approvals

UL Listed File #	E324458
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document