


A1022204-1 Cut Sheet

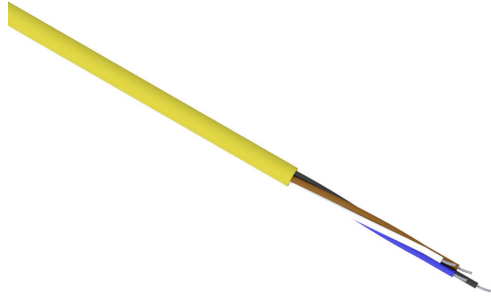

LUTZE IO-Link flexible control cable, unshielded, 4 conductors, 22 AWG, bare copper, PVC/Nylon conductor insulation material, black, brown, blue and white, PVC jacket, yellow, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A1022204-1>

Technical Specifications

Brand	LUTZE
Item	Cable
Series	IO-Link
Protocol	IO-Link
Wire/Cable Type	Control
UL Wire/Cable Type	PLTC-ER, ITC-ER and MTW
Applicable Standards	UL 20886
Application	IO-Link
Flexibility	Flexible
Voltage Rating	300V (Types PLTC-ER, ITC-ER), 600V (Type MTW)
Conductors	4 conductors
Conductor Size	22 AWG
Conductor Stranding	7-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC/Nylon

Conductor Insulation Color	Black, brown, blue and white
Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Yellow
Nominal Overall Cable Diameter	0.276in
Bulk Length	Cut to length
Package Type	1 to 99ft = Coil, 100 to 510ft = 14 x 7in Reel, 511 to 730ft = 14 x 10in Reel, 731 to 1140ft = 16 x 10in Reel, 1141 to 1600ft = 18 x 10in Reel, 1601 to 2080ft = 18 x 13in Reel, 2081 to 2500ft = 24 x 17in Wooden Reel

Agency Approvals

UL Listed File #	E324458
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document