


# A1022205-1 Cut Sheet

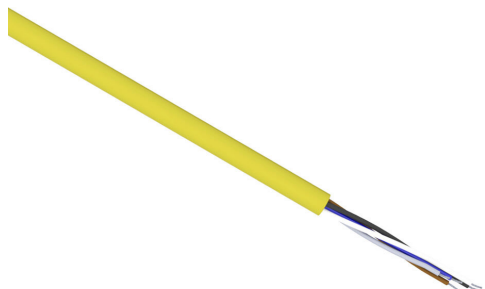

LUTZE IO-Link flexible control cable, unshielded, 5 conductors, 22 AWG, bare copper, PVC/Nylon conductor insulation material, black, brown, blue, white and gray, PVC jacket, yellow, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A1022205-1>

## Technical Specifications

<b>Brand</b>	LUTZE
<b>Item</b>	Cable
<b>Series</b>	IO-Link
<b>Protocol</b>	IO-Link
<b>Wire/Cable Type</b>	Control
<b>UL Wire/Cable Type</b>	PLTC-ER, ITC-ER and MTW
<b>Applicable Standards</b>	UL 20886
<b>Application</b>	IO-Link
<b>Flexibility</b>	Flexible
<b>Voltage Rating</b>	300V (Types PLTC-ER, ITC-ER), 600V (Type MTW)
<b>Conductors</b>	5 conductors
<b>Conductor Size</b>	22 AWG
<b>Conductor Stranding</b>	7-stranded
<b>Conductor Material</b>	Bare copper
<b>Conductor Insulation Material</b>	PVC/Nylon

<b>Conductor Insulation Color</b>	Black, brown, blue, white and gray
<b>Shielding</b>	Unshielded
<b>Jacket Material</b>	PVC
<b>Jacket Color</b>	Yellow
<b>Nominal Overall Cable Diameter</b>	0.3in
<b>Bulk Length</b>	Cut to length
<b>Package Type</b>	<ul style="list-style-type: none"><li>• 20 to 99ft = Coil</li><li>• 100 to 435ft = 14 x 7in Reel</li><li>• 436 to 620ft = 14 x 10in Reel</li><li>• 621 to 950ft = 16 x 10in Reel</li><li>• 951 to 1325ft = 18 x 10in Reel</li><li>• 1326 to 1725ft = 18 x 13in Reel</li><li>• 1726 to 2500ft = 24 x 17in Wooden Reel</li></ul>

## Agency Approvals

<b>UL Listed File #</b>	E324458
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>