


A1040006-1 Cut Sheet

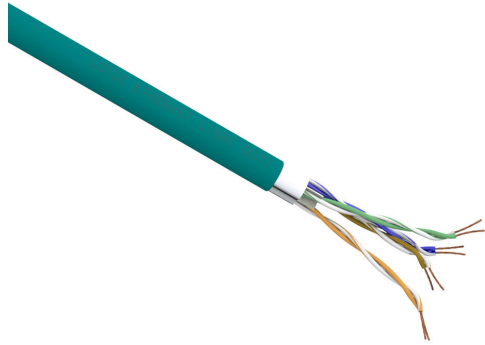

LUTZE Cat6 industrial Ethernet cable, shielded, 4 twisted pairs, 22 AWG, solid, bare copper, HDPE conductor insulation material, PVC jacket, teal, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A1040006-1>

Technical Specifications

Brand	LUTZE
Item	Cable
Protocol	Ethernet
Wire/Cable Type	Cat6 industrial Ethernet
UL Wire/Cable Type	CMR, CMX, PLTC and AWM
Applicable Standards	NFPA 79, UL 21695 and UL 1581
Application	Data
Flexibility	Semi-flexible
Voltage Rating	600V
Conductors	4 twisted pairs
Conductor Size	22 AWG
Conductor Stranding	Solid
Conductor Material	Bare copper
Conductor Insulation Material	High-density polyethylene (HDPE)

Conductor Insulation Color	Pair 1: blue, white/blue, Pair 2: orange, white/orange, Pair 3: green, white/green and Pair 4: brown, white/brown
Shielding	Shielded
Jacket Material	PVC
Jacket Color	Teal
Nominal Overall Cable Diameter	0.368in
Bulk Length	Cut to length
Package Type	1 to 75ft = Coil, 76 to 290ft = 14 x 7in Reel, 291 to 410ft = 14 x 10in Reel, 411 to 630ft = 16 x 10in Reel, 631 to 880ft = 18 x 10in Reel, 881 to 1000ft = 18 x 13in Reel

Agency Approvals

UL Listed File #	E331083
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document