


# A1040006-1 Cut Sheet

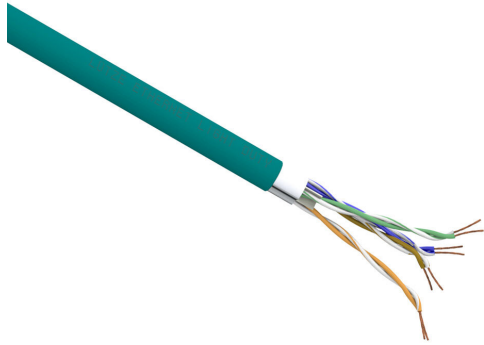

LUTZE Cat6 industrial Ethernet cable, shielded, 4 twisted pairs, 22 AWG, solid, bare copper, HDPE conductor insulation material, PVC jacket, teal, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A1040006-1>

## Technical Specifications

<b>Brand</b>	LUTZE
<b>Item</b>	Cable
<b>Protocol</b>	Ethernet
<b>Wire/Cable Type</b>	Cat6 industrial Ethernet
<b>UL Wire/Cable Type</b>	CMR, CMX, PLTC and AWM
<b>Applicable Standards</b>	NFPA 79, UL 21695 and UL 1581
<b>Application</b>	Data
<b>Flexibility</b>	Semi-flexible
<b>Voltage Rating</b>	600V
<b>Conductors</b>	4 twisted pairs
<b>Conductor Size</b>	22 AWG
<b>Conductor Stranding</b>	Solid
<b>Conductor Material</b>	Bare copper
<b>Conductor Insulation Material</b>	High-density polyethylene (HDPE)

<b>Conductor Insulation Color</b>	Pair 1: blue, white/blue, Pair 2: orange, white/orange, Pair 3: green, white/green and Pair 4: brown, white/brown
<b>Shielding</b>	Shielded
<b>Jacket Material</b>	PVC
<b>Jacket Color</b>	Teal
<b>Nominal Overall Cable Diameter</b>	0.368in
<b>Bulk Length</b>	Cut to length
<b>Package Type</b>	<ul style="list-style-type: none"><li>• 20 to 75ft = Coil</li><li>• 76 to 290ft = 14 x 7in Reel</li><li>• 291 to 410ft = 14 x 10in Reel</li><li>• 411 to 630ft = 16 x 10in Reel</li><li>• 631 to 880ft = 18 x 10in Reel</li><li>• 881 to 1000ft = 18 x 13in Reel</li></ul>

## Agency Approvals

<b>UL Listed File #</b>	E331083
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>