


A1040020-1 Cut Sheet

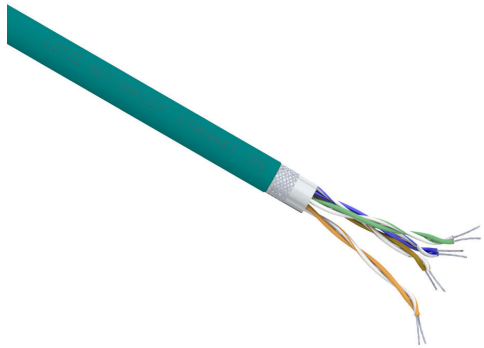

LUTZE MOTIONFLEX continuous flexing Cat5e industrial Ethernet cable, shielded, 4 twisted pairs, 24 AWG, 7-stranded, tinned copper, HDPE conductor insulation material, TPE jacket, teal, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A1040020-1>

Technical Specifications

Brand	LUTZE
Item	Cable
Series	MOTIONFLEX
Protocol	Ethernet
Wire/Cable Type	Cat5e industrial Ethernet
UL Wire/Cable Type	CMR, CMX, CMG and AWM
Applicable Standards	NFPA 79 and UL 2463
Application	Data
Flexibility	Continuous flexing
Voltage Rating	600V
Conductors	4 twisted pairs
Conductor Size	24 AWG
Conductor Stranding	7-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	High-density polyethylene (HDPE)

Conductor Insulation Color	Pair 1: blue, white/blue, Pair 2: orange, white/orange, Pair 3: green, white/green and Pair 4: brown, white/brown
Shielding	Shielded
Jacket Material	TPE
Jacket Color	Teal
Nominal Overall Cable Diameter	0.299in
Bulk Length	Cut to length
Package Type	1 to 99ft = Coil, 100 to 435ft = 14 x 7in Reel, 436 to 625ft = 14 x 10in Reel, 626 to 955ft = 16 x 10in Reel, 956 to 1000ft = 18 x 10in Reel

Agency Approvals

UL Listed File #	E319350
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document