


# A104265-1 Cut Sheet

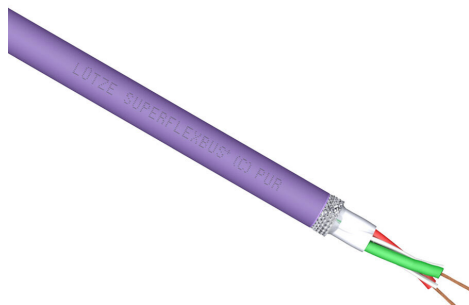

LUTZE continuous flexing Profibus cable, shielded, 1 twisted pair, 24 AWG, 19-stranded, bare copper, special polyolefin conductor insulation material, PUR jacket, purple, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A104265-1>

## Technical Specifications

<b>Brand</b>	LUTZE
<b>Item</b>	Cable
<b>Protocol</b>	Fieldbus
<b>Wire/Cable Type</b>	Profibus
<b>UL Wire/Cable Type</b>	CMX and AWM
<b>Applicable Standards</b>	NFPA 79, UL 1581 and UL 21198
<b>Application</b>	Data
<b>Flexibility</b>	Continuous flexing
<b>Voltage Rating</b>	300V
<b>Conductors</b>	1 twisted pair
<b>Conductor Size</b>	24 AWG
<b>Conductor Stranding</b>	19-stranded
<b>Conductor Material</b>	Bare copper

<b>Conductor Insulation Material</b>	Special polyolefin
<b>Conductor Insulation Color</b>	Red and green
<b>Shielding</b>	Shielded
<b>Jacket Material</b>	PUR
<b>Jacket Color</b>	Purple
<b>Nominal Overall Cable Diameter</b>	0.315in
<b>Bulk Length</b>	Cut to length
<b>Package Type</b>	<ul style="list-style-type: none"><li>• 20 to 99ft = Coil</li><li>• 100 to 395ft = 14 x 7in Reel</li><li>• 396 to 560ft = 14 x 10in Reel</li><li>• 561 to 860ft = 16 x 10in Reel</li><li>• 861 to 1000ft = 18 x 10in Reel</li></ul>

## Agency Approvals

<b>UL Listed File #</b>	E319350
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>