


A104301-1 Cut Sheet

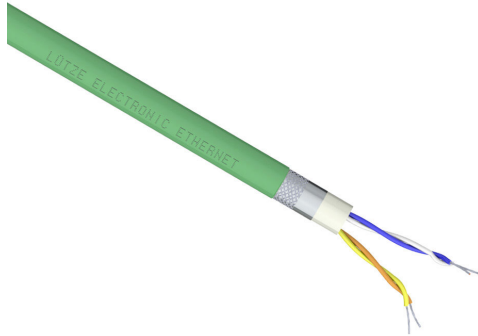

LUTZE flexible Cat5e industrial Ethernet cable, shielded, 2 twisted pairs, 22 AWG, solid, bare copper, special polyolefin conductor insulation material, PVC jacket, green, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A104301-1>

Technical Specifications

Brand	LUTZE
Item	Cable
Protocol	Ethernet
Wire/Cable Type	Cat5e industrial Ethernet
UL Wire/Cable Type	CMG, PLTC and AWM
Applicable Standards	NFPA 79, UL 20201, UL 444, UL 1685 and UL 1581
Application	Data
Flexibility	Flexible
Voltage Rating	600V
Conductors	2 twisted pairs
Conductor Size	22 AWG
Conductor Stranding	Solid
Conductor Material	Bare copper

Conductor Insulation Material	Special polyolefin
Conductor Insulation Color	Pair 1: white, blue and Pair 2: yellow, orange
Shielding	Shielded
Jacket Material	PVC
Jacket Color	Green
Nominal Overall Cable Diameter	0.256in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 99ft = Coil• 100 to 595ft = 14 x 7in Reel• 596 to 850ft = 14 x 10in Reel• 851 to 1000ft = 16 x 10in Reel

Agency Approvals

UL Listed File #	E331083
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document