


A104307-1 Cut Sheet

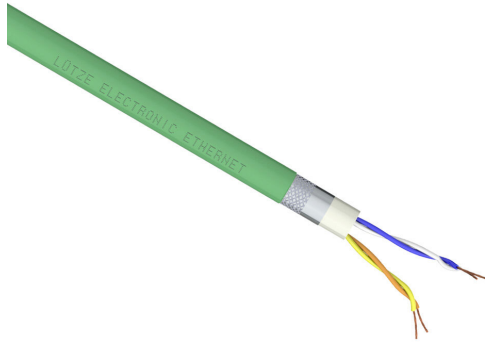

LUTZE flexible Cat5e industrial Ethernet cable, shielded, 2 twisted pairs, 22 AWG, 7-stranded, tinned copper, special polyolefin conductor insulation material, PVC jacket, green, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A104307-1>

Technical Specifications

Brand	LUTZE
Item	Cable
Protocol	Ethernet
Wire/Cable Type	Cat5e industrial Ethernet
UL Wire/Cable Type	CMG, CMX, PLTC and AWM
Applicable Standards	NFPA 79, UL 20201, UL 444 and UL 1685
Application	Data
Flexibility	Flexible
Voltage Rating	600V
Conductors	2 twisted pairs
Conductor Size	22 AWG
Conductor Stranding	7-stranded
Conductor Material	Tinned copper

Conductor Insulation Material	Special polyolefin
Conductor Insulation Color	Pair 1: white, blue and Pair 2: yellow, orange
Shielding	Shielded
Jacket Material	PVC
Jacket Color	Green
Nominal Overall Cable Diameter	0.256in
Bulk Length	Cut to length
Package Type	1 to 99ft = Coil, 100 to 590ft = 14 x 7in Reel, 591 to 850ft = 14 x 10in Reel, 851 to 1000ft = 16 x 10in Reel

Agency Approvals

UL Listed File #	E331083
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document