


A104307-1 Cut Sheet

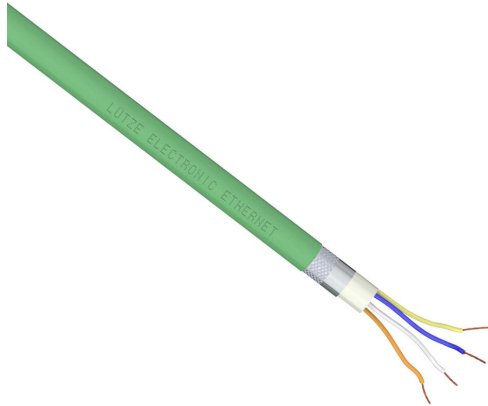

LUTZE flexible PROFINET Type B cable, shielded, 1 star quad, 22 AWG, 7-stranded, tinned copper, special polyolefin conductor insulation material, PVC jacket, green, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A104307-1>

Technical Specifications

Brand	LUTZE
Item	Cable
Protocol	Cat5e Ethernet and fieldbus
Wire/Cable Type	PROFINET Type B
UL Wire/Cable Type	CMG, CMX, PLTC and AWM
Applicable Standards	NFPA 79, UL 20201, UL 444, UL 1685 and IEC 61156
Application	Data
Flexibility	Flexible
Voltage Rating	600V
Conductors	1 star quad
Conductor Size	22 AWG
Conductor Stranding	7-stranded
Conductor Material	Tinned copper

Conductor Insulation Material	Special polyolefin
Conductor Insulation Color	Pair 1: white, blue and Pair 2: yellow, orange
Shielding	Overall aluminized polyester foil and tinned copper braid
Jacket Material	PVC
Jacket Color	Green
Nominal Overall Cable Diameter	0.256in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20-99ft = Coil• 100-595ft = 14 x 7in Reel• 596-850ft = 14 x 10in Reel• 851-1000ft = 16 x 10in Reel

Agency Approvals

UL Listed File #	E331083
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document