


A104349-1 Cut Sheet

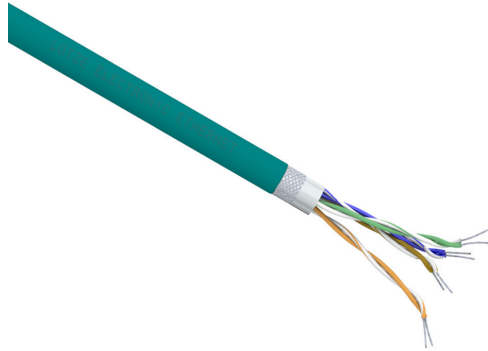

LUTZE flexible Cat5e industrial Ethernet cable, shielded, 4 twisted pairs, 22 AWG, 7-stranded, tinned copper, special polyolefin conductor insulation material, PVC jacket, teal, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A104349-1>

Technical Specifications

Brand	LUTZE
Item	Cable
Protocol	Ethernet
Wire/Cable Type	Cat5e industrial Ethernet
UL Wire/Cable Type	CMG, CMX, PLTC and AWM
Applicable Standards	NFPA 79, UL 2570 and UL 1685
Application	Data
Flexibility	Flexible
Voltage Rating	600V
Conductors	4 twisted pairs
Conductor Size	22 AWG
Conductor Stranding	7-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	Special polyolefin

Conductor Insulation Color	Pair 1: blue, white/blue, Pair 2: orange, white/orange, Pair 3: green, white/green and Pair 4: brown, white/brown
Shielding	Shielded
Jacket Material	PVC
Jacket Color	Teal
Nominal Overall Cable Diameter	0.338in
Bulk Length	Cut to length
Package Type	1 to 75ft = Coil, 76 to 340ft = 14 x 7in Reel, 341 to 490ft = 14 x 10in Reel, 491 to 750ft = 16 x 10in Reel, 751 to 1000ft = 18 x 10in Reel

Agency Approvals

UL Listed File #	E331083
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document