


A1061804-1 Cut Sheet

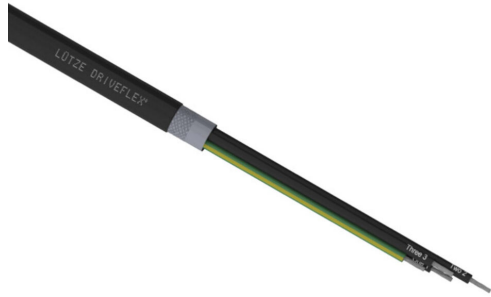

LUTZE DRIVEFLEX VFD cable, 4 conductors (includes ground), 18 AWG, 19-stranded, tinned copper, XLPE conductor insulation material, XHHW-2 jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A1061804-1>

Technical Specifications

Brand	LUTZE
Item	Cable
Series	DRIVEFLEX
Wire/Cable Type	VFD
UL Wire/Cable Type	TC-ER-JP and WTTTC
Applicable Standards	UL 1277
Application	Drive and motor
Flexibility	Semi-flexible
Voltage Rating	600V (Type TC-ER-JP), 1000V (Type WTTTC, Flexible Motor Supply Cable)
Conductors	4 conductors (includes ground)
Conductor Size	18 AWG
Conductor Stranding	19-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	XLPE

Conductor Insulation Color	Black with white numbers and green/yellow ground
Shielding	Overall foil and braid shielded
Jacket Material	XHHW-2
Jacket Color	Black
Nominal Overall Cable Diameter	0.415in
Bulk Length	Cut to length
Package Type	1 to 50ft = Coil, 51 to 220ft = Coil, 221 to 320ft = 14 x 7in Reel, 321 to 500ft = 14 x 10in Reel, 501 to 700ft = 16 x 10in Reel, 701 to 920ft = 18 x 10in Reel, 921 to 1970ft = 18 x 13in Reel, 1971 to 3250ft = 24 x 17in Wooden Reel, 3251 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	E352875
UL Recognized File #	None
UL Hazardous File #	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement