


A3031625-1 Cut Sheet

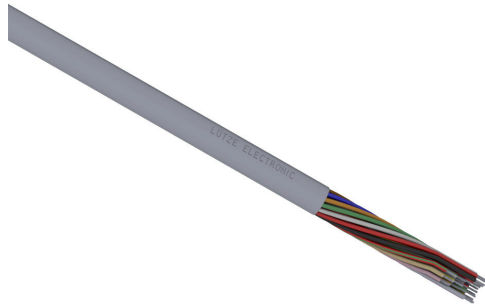

LUTZE ELECTRONIC flexible control and signal cable, unshielded, 25 conductors, 16 AWG, 26-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A3031625-1>

Technical Specifications

Brand	LUTZE	Shielding	Unshielded
Item	Cable	Jacket Material	PVC
Series	ELECTRONIC	Jacket Color	Gray
Wire/Cable Type	Control and signal	Nominal Overall Cable Diameter	0.669in
UL Wire/Cable Type	PLTC, AWM and CM	Bulk Length	Cut to length
Applicable Standards	UL 2464	Package Type <ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 85ft = 14 x 7in Reel• 86 to 125ft = 14 x 10in Reel• 126 to 190ft = 16 x 10in Reel• 191 to 265ft = 18 x 10in Reel• 266 to 345ft = 18 x 13in Reel• 346 to 775ft = 24 x 17in Wooden Reel• 776 to 1240ft = 30 x 17in Wooden Reel• 1241 to 2500ft = Large Wooden Reel	
Application	General purpose and food and beverage		
Flexibility	Flexible		
Voltage Rating	300V		
Conductors	25 conductors		
Conductor Size	16 AWG		
Conductor Stranding	26-stranded		
Conductor Material	Tinned copper		
Conductor Insulation Material	PVC		
Conductor Insulation Color	Black, red, white, green, orange, blue, brown, yellow, violet, gray, pink, tan, red/green, red/yellow, red/black, white/black, white/red, white/green, white/yellow, white/blue, white/brown, white/orange, white/gray, white/violet and white/black/red		

Agency Approvals

UL Listed File #	E331083
CE	View CE declarations
CSA File #	LL41103
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document