


A3081403-1 Cut Sheet

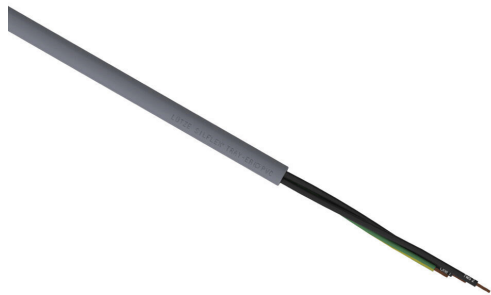

LUTZE Silflex flexible control cable, unshielded, 3 conductors (includes ground), 14 AWG, bare copper, PVC/Nylon conductor insulation material, black with white numbers and green/yellow ground, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A3081403-1>

Technical Specifications

Brand	LUTZE	Shielding	Unshielded
Item	Cable	Jacket Material	PVC
Series	Silflex	Jacket Color	Gray
Wire/Cable Type	Control	Nominal Overall Cable Diameter	0.348in
UL Wire/Cable Type	TC, TC-ER, WTTC and MTW	Bulk Length	Cut to length
Application	General purpose	Package Type	1 to 75ft = Coil, 76 to 320ft = 14 x 7in Reel, 321 to 460ft = 14 x 10in Reel, 461 to 705ft = 16 x 10in Reel, 706 to 985ft = 18 x 10in Reel, 986 to 1280ft = 18 x 13in Reel, 1281 to 2865ft = 24 x 17in Wooden Reel, 2866 to 4590ft = 30 x 17in Wooden Reel, 4591 to 10000ft = Large Wooden Reel
Flexibility	Flexible		
Voltage Rating	600V (Types TC, TC-ER, MTW), 1000V (Type WTTC)		
Conductors	3 conductors (includes ground)		
Conductor Size	14 AWG		
Conductor Stranding	41-stranded		
Conductor Material	Bare copper		
Conductor Insulation Material	PVC/Nylon		
Conductor Insulation Color	Black with white numbers and green/yellow ground		

Agency Approvals

UL Listed File #	E324630
UL Recognized File #	none
UL Hazardous File #	none
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement