


A3081603-1 Cut Sheet

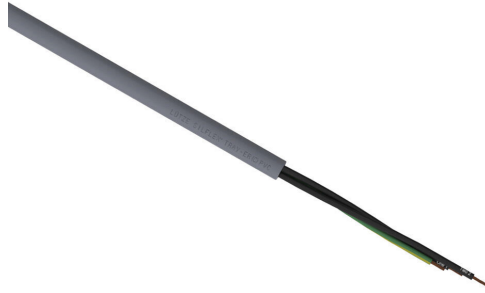

LUTZE Silflex flexible control cable, unshielded, 3 conductors (includes ground), 16 AWG, bare copper, PVC/Nylon conductor insulation material, black with white numbers and green/yellow ground, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A3081603-1>

Technical Specifications

Brand	LUTZE
Item	Cable
Series	Silflex
Wire/Cable Type	Control
UL Wire/Cable Type	TC, TC-ER, WTTC and MTW
Application	General purpose
Flexibility	Flexible
Voltage Rating	600V (Types TC, TC-ER, MTW), 1000V (Type WTTC)
Conductors	3 conductors (includes ground)
Conductor Size	16 AWG
Conductor Stranding	26-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC/Nylon
Conductor Insulation Color	Black with white numbers and green/yellow ground

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.321in
Bulk Length	Cut to length
Package Type	1 to 50ft = Coil, 51 to 99ft = 14 x 7in Reel, 100 to 430ft = 14 x 10in Reel, 431 to 610ft = 16 x 10in Reel, 611 to 950ft = 18 x 10in Reel, 951 to 1340ft = 18 x 13in Reel, 1341 to 1750ft = 24 x 17in Wooden Reel, 1751 to 3760ft = 30 x 17in Wooden Reel, 3761 to 5000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E324630
UL Recognized File #	none
UL Hazardous File #	none
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement